

Part No: 1631-015CLSR

Valves

Y-Check Valve

Desc: 1-1/2 PVC CLR Y-CHECK VALVE SRFPT FKM

MSRP: 357.12

Part Code: 628

Weight(lbs): 2.196

Weight(kg): 0.996

Weight(gm): 996

Size: 1-1/2"


Color: CLEAR

Material: PVC

Connection SR Fipt

Body Color Clear

O-Ring FKM

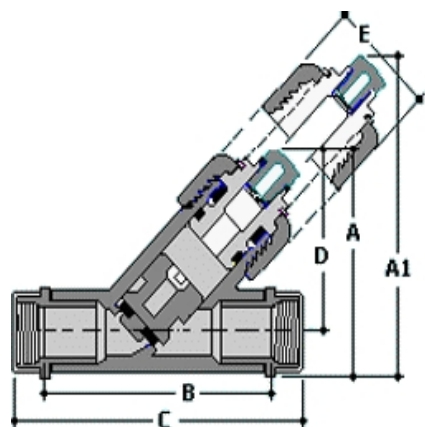

A = 6- 9/32

A1 = 7-25/32

B = 7- 5/32

C = 8- 7/8

D = 4- 7/8

E = 3- 5/32

Cv = 50.7
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

