

**Part No:** 1632-012CL

**Valves**

**Y-Check Valve**

**Desc:** 1-1/4 PVC CLEAR Y-CHECK VALVE SOC FKM

**MSRP:** 305.76

**Part Code:** 628

**Weight(lbs):** 1.076

**Weight(kg):** 0.488

**Weight(gm):** 488

**Size:** 1-1/4"


**Color:** CLEAR

**Material:** PVC

**Connection** Socket

**Body Color** Clear

**O-Ring** FKM

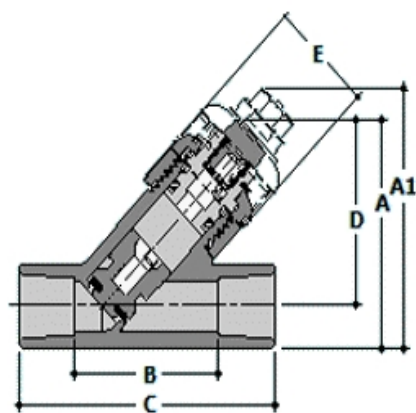

A = 5- 5/16

A1 = 6- 1/2

B = 3- 1/32

C = 5- 9/16

D = 4- 9/32

E = 2-13/16

Cv = 33.8  
Values

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

