

**Part No:** 1632-020CL

**Valves**

**Y-Check Valve**

**Desc:** 2 PVC CLEAR Y-CHECK VALVE SOC FKM

**MSRP:** 413.98

**Part Code:** 628

**Weight(lbs):** 2.921

**Weight(kg):** 1.325

**Weight(gm):** 1325

**Size:** 2"


**Color:** CLEAR

**Material:** PVC

**Connection** Socket

**Body Color** Clear

**O-Ring** FKM

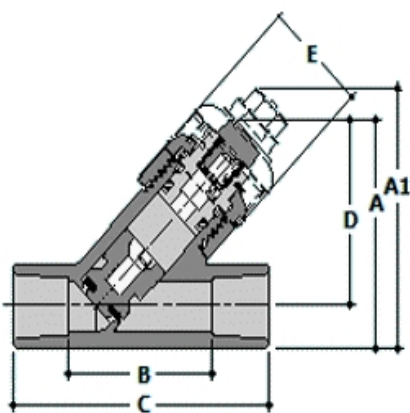

A = 6-29/32

A1 = 8-15/32

B = 4-31/32

C = 7- 1/2

D = 5- 1/2

E = 3-23/32

Cv = 79.2  
Values

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

