

Part No: 163A-012CL

Valves

Y-Check Valve

Desc: 1-1/4 PVC CLR T/U Y-CHECK VLVE SOC FKM

MSRP: 332.79

Part Code: 628

Weight(lbs): 1.909

Weight(kg): 0.866

Weight(gm): 866

Size: 1-1/4"


Color: CLEAR

Material: PVC

Connection Socket (True Union)

Body Color Clear

O-Ring FKM

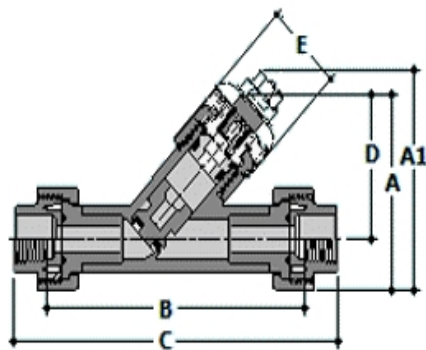

A = 5-13/16

A1 = 7- 1/16

B = 7- 7/16

C = 10- 1/8

D = 4- 9/32

E = 2-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

