

**Part No:** 163B-005SR

**Valves**

**Y-Check Valve**

**Desc:** 1/2 PVC T/U Y-CHECK VALVE SRFPT FKM

**MSRP:** 184

**Part Code:** 627

**Weight(lbs):** 0.593

**Weight(kg):** 0.269

**Weight(gm):** 269

**Size:** 1/2"


**Color:** GRAY

**Material:** PVC

**Connection** SR Fipt (True Union)

**Body Color** Gray

**O-Ring** FKM

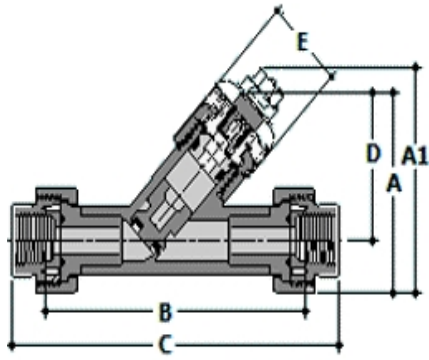

A = 3- 1/2

A1 = 4- 3/8

B = 5- 1/2

C = 7

D = 2-19/32

E = 1- 5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

