

Part No: 163B-015CLSR

Valves

Y-Check Valve

Desc: 1-1/2 PVC CLR T/U Y-CHECK VLVE SRFPT FKM

MSRP: 389.6

Part Code: 628

Weight(lbs): 2.934

Weight(kg): 1.331

Weight(gm): 1331

Size: 1-1/2"


Color: CLEAR

Material: PVC

Connection SR Fipt (True Union)

Body Color Clear

O-Ring FKM

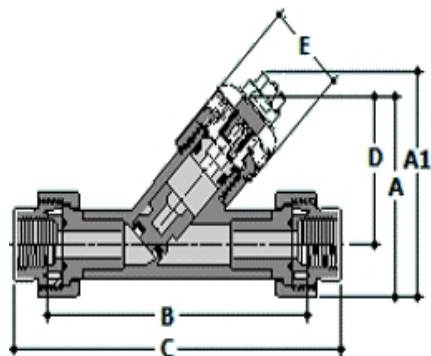

A = 6- 5/8

A1 = 8- 1/8

B = 9

C = 11- 1/16

D = 4- 7/8

E = 3- 5/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

