

Part No: 172B-005CSR

Valves

Y-Pattern Valve

Desc: 1/2 CPVC T/U Y-PATTERN VALVE SRFPT EPDM

MSRP: 238.09

Part Code: 622

Weight(lbs): 0.725

Weight(kg): 0.329

Weight(gm): 329

Size: 1/2"


Color: GRAY

Material: CPVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring EPDM

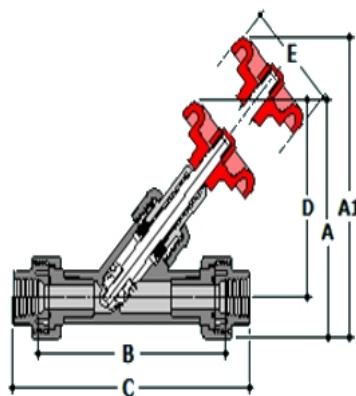

A = 5-13/16

A1 = 7

B = 5- 1/2

C = 7

D = 4- 1/4

E = 2- 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

