

Part No: 172B-007CSR

Valves

Y-Pattern Valve

Desc: 3/4 CPVC T/U Y-PATTERN VALVE SRFPT EPDM

MSRP: 284.04

Part Code: 622

Weight(lbs): 1.109

Weight(kg): 0.503

Weight(gm): 503

Size: 3/4"


Color: GRAY

Material: CPVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring EPDM

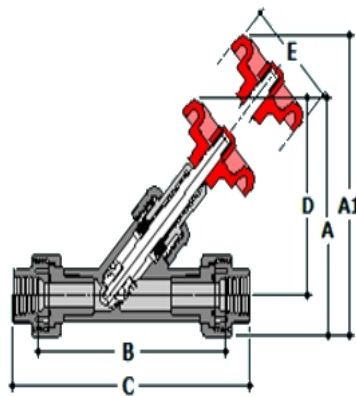

A = 6

A1 = 8- 3/16

B = 6- 7/16

C = 7- 7/8

D = 4- 7/8

E = 2- 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

