

Part No: 172B-012C

Valves

Y-Pattern Valve

Desc: 1-1/4 CPVC T/U Y-PATTERN VALVE FPT EPDM

MSRP: 294.69

Part Code: 622

Weight(lbs): 2.535

Weight(kg): 1.15

Weight(gm): 1150

Size: 1-1/4"


Color: CLEAR

Material: CPVC

Connection Fipt (True Union)

Body Color Gray

O-Ring EPDM

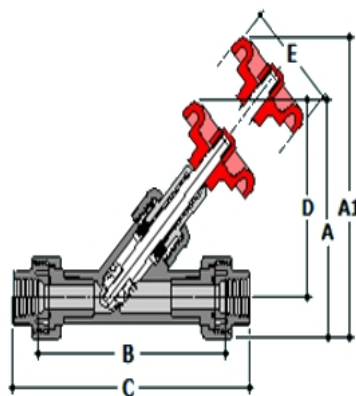

A = 8-3/16

A1 = 11-1/2

B = 6-3/16

C = 10-1/8

D = 6-5/8

E = 3-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

