

Part No: 172B-012CSR

Valves

Y-Pattern Valve

Desc: 1-1/4 CPVC T/U Y-PATTERN VLVE SRFPT EPDM

MSRP: 306.57

Part Code: 622

Weight(lbs): 2.575

Weight(kg): 1.168

Weight(gm): 1168

Size: 1-1/4"


Color: GRAY

Material: CPVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring EPDM

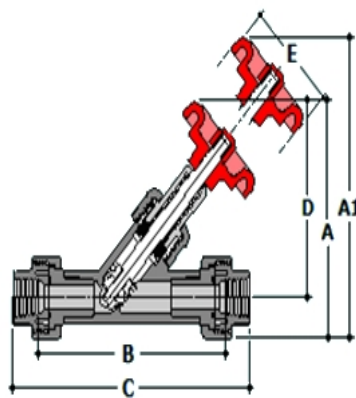

A = 8- 3/16

A1 = 11- 1/2

B = 6- 3/16

C = 10- 1/8

D = 6- 5/8

E = 3- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

