

Part No: 172B-015CSR

Valves

Y-Pattern Valve

Desc: 1-1/2 CPVC T/U Y-PATTERN VLVE SRFPT EPDM

MSRP: 421.27

Part Code: 622

Weight(lbs): 3.384

Weight(kg): 1.535

Weight(gm): 1535

Size: 1-1/2"


Color: GRAY

Material: CPVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring EPDM

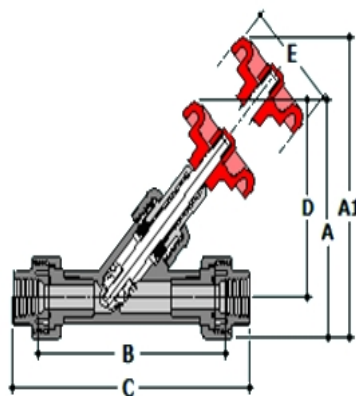

A = 9- 3/8

A1 = 12-13/16

B = 9

C = 10-15/16

D = 7- 9/16

E = 3- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

