

Part No: 172B-030CLSR

Valves

Y-Pattern Valve

Desc: 3 PVC CLR T/U Y-PATTERN VALVE SRFPT EPDM

MSRP: 1244.52

Part Code: 621

Weight(lbs): 14.151

Weight(kg): 6.419

Weight(gm): 6419

Size: 3"


Color: CLEAR

Material: PVC

Connection SR Fipt (True Union)

Body Color Clear

O-Ring EPDM

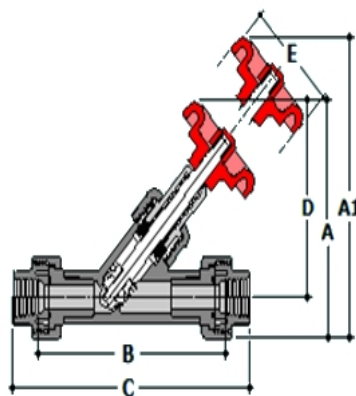

A = 15- 5/8

A1 = 21- 1/8

B = 15- 3/8

C = 18- 3/16

D = 12- 1/2

E = 6- 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

