

Part No: 172B-040SR

Valves

Y-Pattern Valve

Desc: 4 PVC T/U Y-PATTERN VALVE SRFPT EPDM

MSRP: 2056.24

Part Code: 620

Weight(lbs): 22.507

Weight(kg): 10.209

Weight(gm): 10209

Size: 4"


Color: GRAY

Material: PVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring EPDM

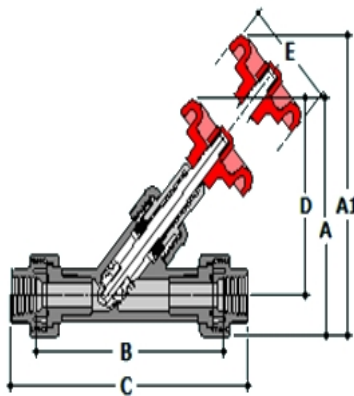

A = 19- 7/16

A1 = 25

B = 19- 1/4

C = 22- 5/16

D = 15- 5/8

E = 7-15/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

