

**Part No:** 1732-012CL

**Valves**

**Y-Pattern Valve**

**Desc:** 1-1/4 PVC CLEAR Y-PATTERN VALVE SOC FKM

**MSRP:** 265.16

**Part Code:** 621

**Weight(lbs):** 1.459

**Weight(kg):** 0.662

**Weight(gm):** 662

**Size:** 1-1/4"

**Color:** CLEAR


**Material:** PVC

**Connection** Socket

**Body Color** Clear

**O-Ring** FKM

**Pressure Rating** 150 psi @ 73° F

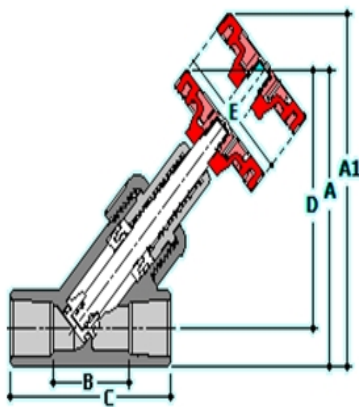

**A** = 7- 5/8

**A1** = 10-15/16

**B** = 3- 1/16

**C** = 5- 9/16

**D** = 6- 1/2

**E** = 3- 1/2

**Cv** = 33.8  
**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

