

**Part No:** 173A-010C

**Valves**

**Y-Pattern Valve**

**Desc:** 1 CPVC T/U Y-PATTERN VALVE SOC FKM

**MSRP:** 255.13

**Part Code:** 622

**Weight(lbs):** 1.488

**Weight(kg):** 0.675

**Weight(gm):** 675

**Size:** 1"


**Color:** GRAY

**Material:** CPVC

**Connection** Socket (True Union)

**Body Color** Gray

**O-Ring** FKM

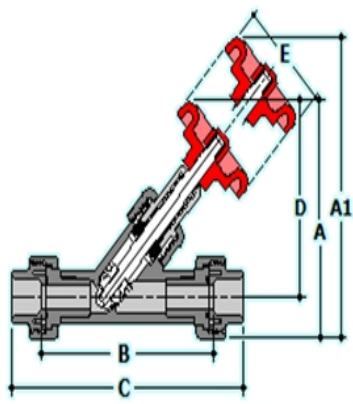

**A** = 6- 5/8

**A1** = 9- 1/8

**B** = 6- 1/2

**C** = 8- 3/4

**D** = 5- 3/8

**E** = 2- 5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

