

**Part No:** 173A-012

**Valves**

**Y-Pattern Valve**

**Desc:** 1-1/4 PVC T/U Y-PATTERN VALVE SOC FKM

**MSRP:** 227.45

**Part Code:** 620

**Weight(lbs):** 2.282

**Weight(kg):** 1.035

**Weight(gm):** 1035

**Size:** 1-1/4"


**Color:** GRAY

**Material:** PVC

**Connection** Socket (True Union)

**Body Color** Gray

**O-Ring** FKM

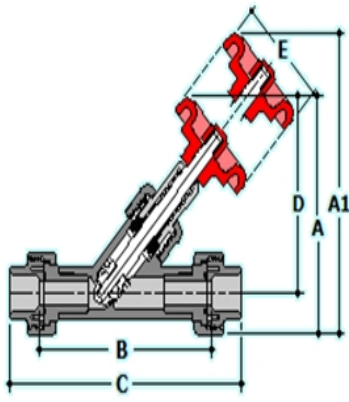

**A** = 8- 3/16

**A1** = 11- 1/2

**B** = 7- 7/16

**C** = 9-15/16

**D** = 6- 5/8

**E** = 3- 1/2

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

