

Part No: 173B-012CSR

Valves

Y-Pattern Valve

Desc: 1-1/4 CPVC T/U Y-PTTRN VALVE SRFPT FKM

MSRP: 330.28

Part Code: 622

Weight(lbs): 2.511

Weight(kg): 1.139

Weight(gm): 1139

Size: 1-1/4"


Color: GRAY

Material: CPVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring FKM

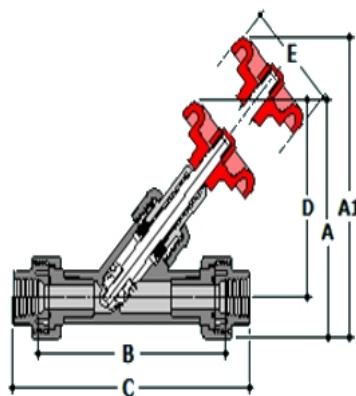

A = 8- 3/16

A1 = 11- 1/2

B = 6- 3/16

C = 10- 1/8

D = 6- 5/8

E = 3- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

