

Part No: 173B-020C

Valves

Y-Pattern Valve

Desc: 2 CPVC T/U Y-PATTERN VALVE FPT FKM

MSRP: 808.98

Part Code: 622

Weight(lbs): 5.408

Weight(kg): 2.453

Weight(gm): 2453

Size: 2"


Color: GRAY

Material: CPVC

Connection Fipt (True Union)

Body Color Gray

O-Ring FKM

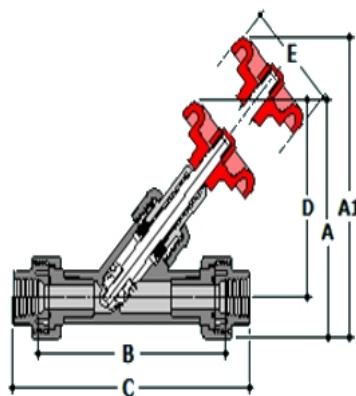

A = 10-11/16

A1 = 14-9/16

B = 10-13/16

C = 12-13/16

D = 8-5/8

E = 3-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

