

Part No: 173B-040CSR

Valves

Y-Pattern Valve

Desc: 4 CPVC T/U Y-PATTERN VALVE SRFPT FKM

MSRP: 3122.26

Part Code: 622

Weight(lbs): 25.349

Weight(kg): 11.498

Weight(gm): 11498

Size: 4"


Color: GRAY

Material: CPVC

Connection SR Fipt (True Union)

Body Color Gray

O-Ring FKM

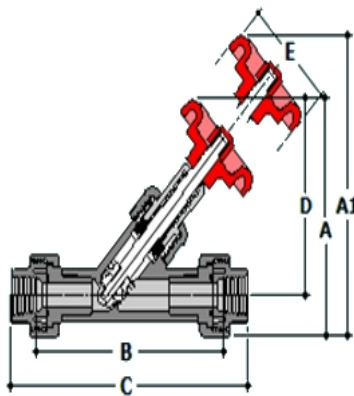

A = 19- 7/16

A1 = 25

B = 19- 1/4

C = 22- 5/16

D = 15- 5/8

E = 7-15/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

