

Part No: 1821V-030CSR

Valves

True Union Ball Valve

Desc: 3 CPVC TU2K IND BV SR/THD EPDM VENTED

MSRP: 1192.24

Part Code: 603

Weight(lbs): 8.497


Weight(kg): 3.854

Weight(gm): 3854

Size: 3

Color: GRAY

Material: CPVC

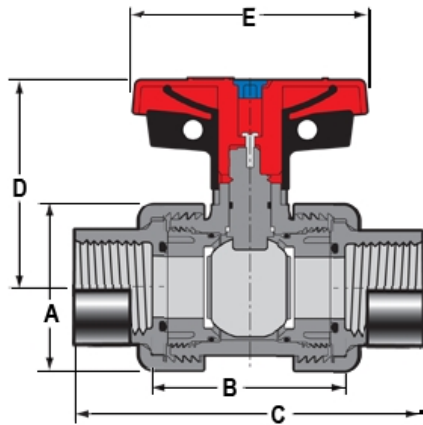

A = 6-1/8

B = 7

C = 9-7/8

D = 5-7/8

E = 7-5/8

Type TU 2000 - Industrial

O-Ring EPDM

Connection SR Fipt (Vented)

Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

