

Part No: 1822-010CFG

FlameGuard®

Drain Valves

Desc: 1 CPVC TU2K INDBV SXS CPVCXFLMGRDCPVC

MSRP: 127.17

Part Code: 077

Weight(lbs): 0.831


Weight(kg): 0.377

Weight(gm): 377

Size: 1

Color: Gray/Orange

Material: CPVC

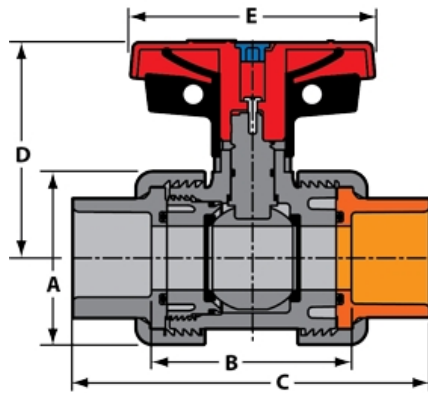

Connection Socket x Socket

Type Industrial

O-Ring EPDM

Note Not UL® Listed

A = 2-5/8

B = 2-15/16

C = 5-3/16

D = 3-1/8

E = 3-7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

