

Part No: 1822V-030C

Valves

True Union Ball Valve

Desc: 3 CPVC TU2K IND BALL VLV SOC EPDM VENTED

MSRP: 1144.46

Part Code: 603

Weight(lbs): 8.356


Weight(kg): 3.79

Weight(gm): 3790

Size: 3

Color: GRAY

Material: CPVC

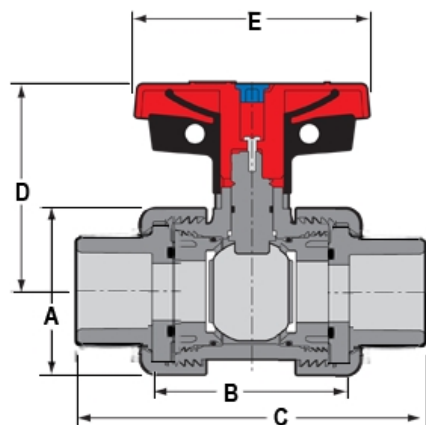

A = 6- 3/16

B = 6- 7/8

C = 10-11/16

D = 5- 7/8

E = 7- 5/8

Cv = 1416

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

