

Part No: 1822V-040

Valves

True Union Ball Valve

Desc: 4 PVC TU2K IND BALL VLV SOC EPDM VENTED

MSRP: 1107.19

Part Code: 601

Weight(lbs): 13.761


Weight(kg): 6.242

Weight(gm): 6242

Size: 4

Color: GRAY

Material: PVC

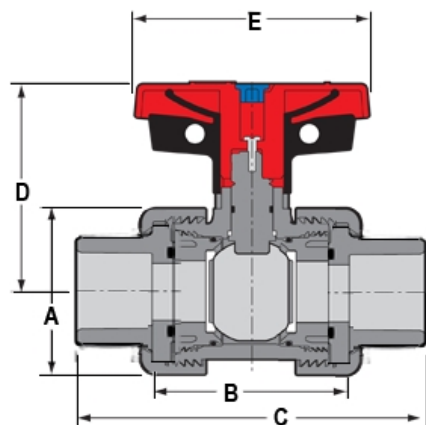

Type TU 2000 - Industrial
O-Ring EPDM
Connection Socket (Vented)
Pressure Rating 235 psi @ 73° F

Cv = 2865
Values

D = 6- 3/4

E = 9- 3/16

A = 7- 3/4

B = 7- 1/2

C = 12

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

