

Part No: 1829-005BL

Low Extractable

Valves

Desc: 1/2 PVC LE TU2K IND BV SOC/FPT EPDM

MSRP: 157.1

Part Code: 066

Weight(lbs): 0.439


Weight(kg): 0.199

Weight(gm): 199

Size: 1/2"

Color: BLUE

Material: PVC LE

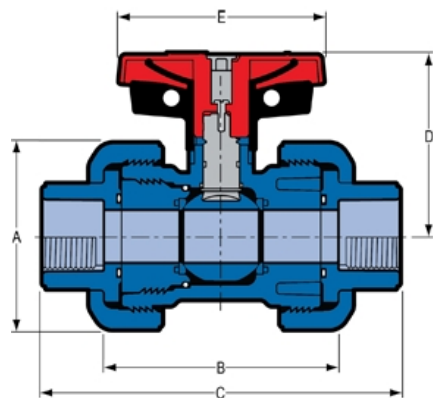

Type TU 2000 Ind Ball Valve
Connection Fipt + Socket
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

A = 1-15/16

B = 2-1/2

C = 4-1/4

D = 2- 9/16

E = 2-7/8

Cv = 29

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

