

**Part No:** 182901-010

**Valves**

**True Union Ball Valve**

**Desc:** 1 PVC TEE VALVE SOC/FPT EPDM

**MSRP:** 223.09

**Part Code:** 263

**Weight(lbs):** 1.768

**Weight(kg):** 0.802

**Weight(gm):** 802

**Size:** 1"

**Color:** GRAY


**Material:** PVC

**Type** TU 2000 - Tee Style

**O-Ring** EPDM

**Connection** Mainline Tee x Socket/Fipt

**Pressure Rating** 235 psi @ 73° F

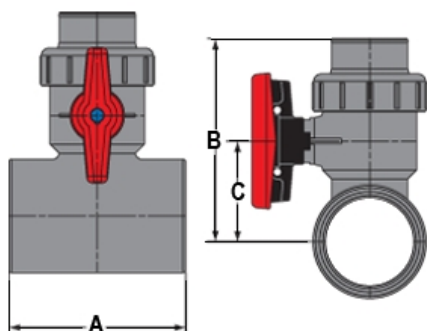

**A** = 4

**B** = 4-11/16

**C** = 2- 1/16

**Cv** = 120  
**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

