

Part No: 182901-010C

Valves

True Union Ball Valve

Desc: 1 CPVC TEE VALVE SOC/FPT EPDM

MSRP: 470.23

Part Code: 264

Weight(lbs): 1.695

Weight(kg): 0.769

Weight(gm): 769

Size: 1"

Color: GRAY


Material: CPVC

Type TU 2000 - Tee Style

O-Ring EPDM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

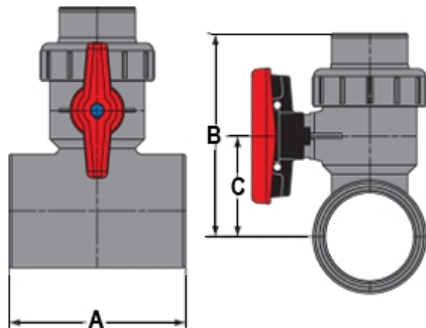

A = 4

B = 4-11/16

C = 2- 1/16

Cv = 120
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

