

**Part No:** 182901-012BL

**Low Extractable**

**Valves**

**Desc:** 1-1/4 PVC LE TEE VALVE SOC/FPT EPDM

**MSRP:** 620.46

**Part Code:** 066

**Weight(lbs):** 1.629


**Weight(kg):** 0.739

**Weight(gm):** 739

**Size:**

**Color:** BLUE

**Material:** PVC LE

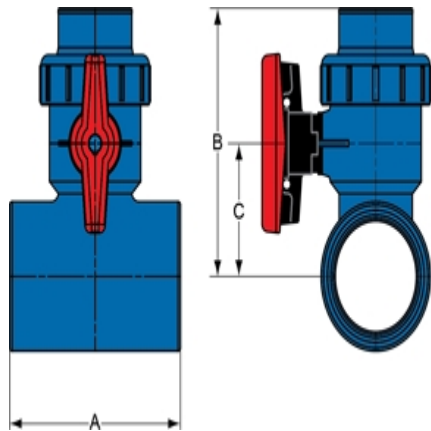

**A** = 4-1/4

**B** = 5-5/16

**C** = 2-7/16

**Type** TU 2000 TEE-Style Valve  
**Connection** Mainline Tee X Socket/Fipt  
**O-Ring** EPDM  
**Pressure Rating** 235 psi @ 73° F

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

