

Part No: 182901-101BL

Low Extractable

Valves

Desc: 3/4X1/2 PVC LE TEE VALVE SOC/FPT EPDM

MSRP: 446.56

Part Code: 066

Weight(lbs): 0.761


Weight(kg): 0.345

Weight(gm): 345

Size: 3/4 X 1/2

Color: BLUE

Material: PVC LE

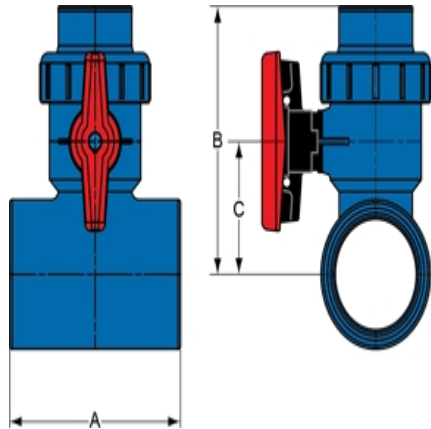

A = 3-3/16

B = 3-7/8

C = 1-3/4

Type TU 2000 TEE-Style Valve
Connection Mainline Tee X Socket/Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

