

Part No: 182901-167

Valves

True Union Ball Valve

Desc: 1-1/4X3/4 PVC TEE VALVE SOC/FPT EPDM

MSRP: 310.8

Part Code: 263

Weight(lbs): 0.97

Weight(kg): 0.44

Weight(gm): 440

Size: 1-1/4"X3/4"

Color: GRAY


Material: PVC

Type TU 2000 - Tee Style

O-Ring EPDM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

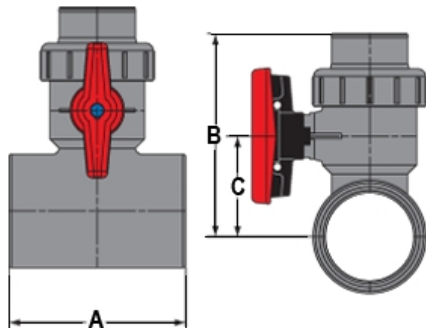

A = 4- 1/4

B = 4- 1/4

C = 1- 7/8

Cv = 63
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

