

Part No: 182901-337

Valves

True Union Ball Valve

Desc: 3X1-1/2 PVC TEE VALVE SOC/FPT EPDM

MSRP: 359.55

Part Code: 263

Weight(lbs): 4.052

Weight(kg): 1.838

Weight(gm): 1838

Size: 3"X1-1/2"

Color: GRAY


Material: PVC

Type TU 2000 - Tee Style

O-Ring EPDM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

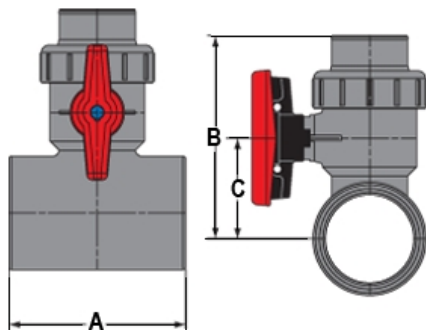

A = 7- 1/4

B = 6- 9/16

C = 3- 7/16

Cv = 357
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

