

Part No: 182901-337BL

Low Extractable

Valves

Desc: 3X1-1/2 PVC LE TEE VALVE SOC/FPT EPDM

MSRP: 1365.73

Part Code: 066

Weight(lbs): 4.015


Weight(kg): 1.821

Weight(gm): 1821

Size: 3 X 1-1/2

Color: BLUE

Material: PVC LE

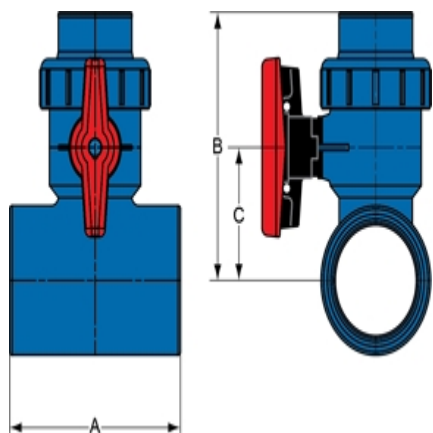

A = 7-1/4

B = 6-9/16

C = 3-7/16

Type TU 2000 TEE-Style Valve

Connection Mainline Tee X Socket/Fipt

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

