

**Part No:** 1831V-040SR

**Valves**

**True Union Ball Valve**

**Desc:** 4 PVC TU2K IND B/V SR/FPT FKM VENTED

**MSRP:** 1503.08

**Part Code:** 601

**Weight(lbs):** 13.686


**Weight(kg):** 6.208

**Weight(gm):** 6208

**Size:** 4

**Color:** GRAY

**Material:** PVC

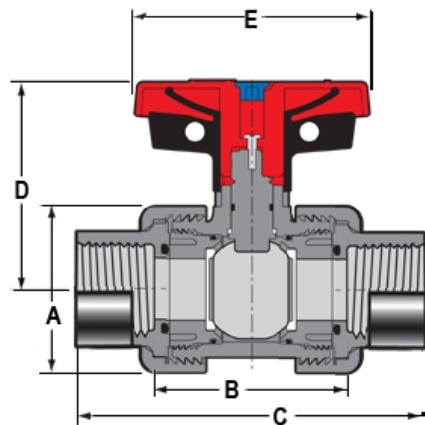

**A** = 7- 1/2

**B** = 7- 1/4

**C** = 10- 1/4

**D** = 6- 3/4

**E** = 9- 3/16

**Cv** = 2865

**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

