

Part No: 1832-040BL

Low Extractable

Valves

Desc: 4 PVC LE TU2K IND BALL VALVE SOC FKM

MSRP: 2309.07

Part Code: 066

Weight(lbs): 14.553


Weight(kg): 6.601

Weight(gm): 6601

Size: 4"

Color: BLUE

Material: PVC LE

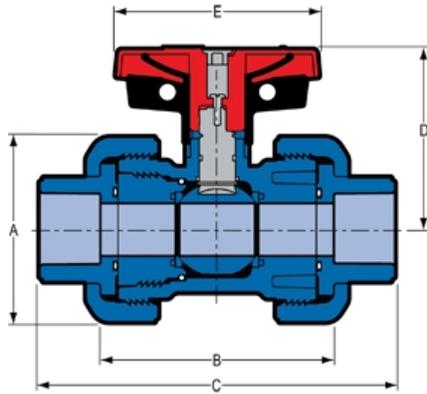

Type TU 2000 Ind Ball Valve  
 Connection Socket  
 O-Ring FKM  
 Pressure Rating 235 psi @ 73° F

A = 7-3/4

B = 7-3/8

C = 11-7/8

D = 6-3/4


E = 9

Cv = 2865  
 Values

**Injection Molded Dimension References:**

- G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L = Overall length of fittings; ± 1/16 inch.
- M = Outside diameter of socket/thread hub; ± 1/16 inch.
- N = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W = Height of cap; ± 1/16 inch

**Typical Molded Dimension References**

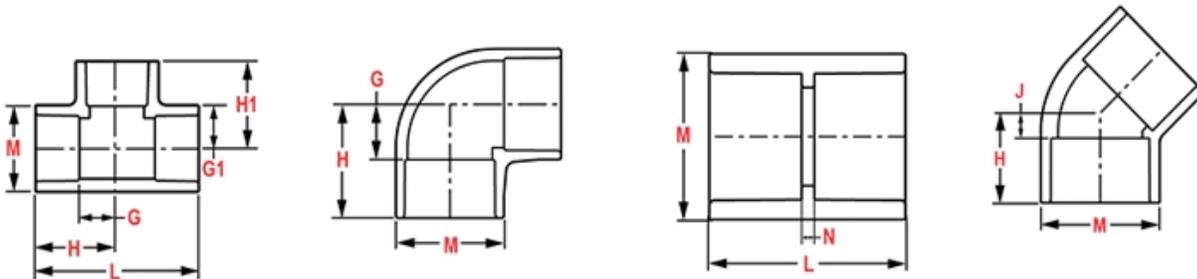

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006