

Part No: 1832V-030C

Valves

True Union Ball Valve

Desc: 3 CPVC TU2K IND BALL VLV SOC FKM VENTD

MSRP: 929.63

Part Code: 603

Weight(lbs): 8.4


Weight(kg): 3.81

Weight(gm): 3810

Size: 3

Color: GRAY

Material: CPVC

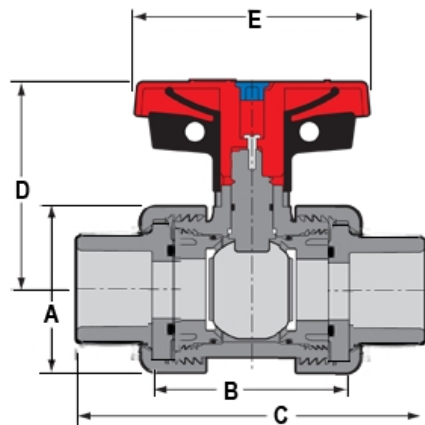

A = 6-3/16

B = 6-7/8

C = 10-11/16

D = 5-7/8

E = 7-5/8

Cv = 1416

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

