

Part No: 1833V-020C

Valves

True Union Ball Valve

Desc: 2 CPVC TU2K IND BV FLANGED FKM VENTED

MSRP: 840.97

Part Code: 602

Weight(lbs): 4.89


Weight(kg): 2.218

Weight(gm): 2218

Size: 2

Color: GRAY

Material: CPVC

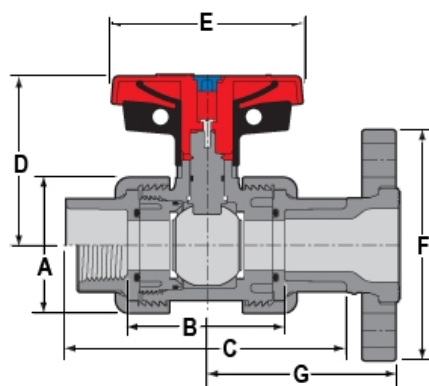

Type TU 2000 - Industrial
O-Ring FKM
Connection Flanged (Vented)
Pressure Rating 150 psi @ 73° F

A = 4- 1/4

B = 4- 3/4

C = 7- 3/4

D = 4- 1/2

E = 5- 1/8

F = 6

G = 5- 1/4

Cv = 395

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

