

Part No: 1833V-025

Valves

True Union Ball Valve

Desc: 2-1/2 PVC TU2K IND BV FLNGED FKM VENTD

MSRP: 951.84

Part Code: 601

Weight(lbs): 11.327


Weight(kg): 5.138

Weight(gm): 5138

Size: 2-1/2

Color: GRAY

Material: PVC

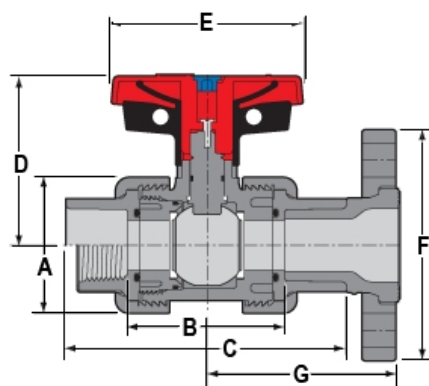

Type TU 2000 - Industrial
O-Ring FKM
Connection Flanged (Vented)
Pressure Rating 150 psi @ 73° F

A = 5- 3/8

B = 5- 7/8

C = 9- 5/16

D = 5- 7/8

E = 7- 5/8

F = 7- 1/2

G = 6

Cv = 579
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

