

Part No: 1833V-030C

Valves

True Union Ball Valve

Desc: 3 CPVC TU2K IND BV FLANGED FKM VENTED

MSRP: 1971.31

Part Code: 603

Weight(lbs): 11.909


Weight(kg): 5.402

Weight(gm): 5402

Size: 3

Color: GRAY

Material: CPVC

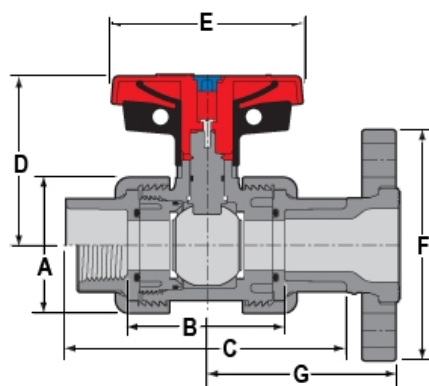

Type TU 2000 - Industrial
O-Ring FKM
Connection Flanged (Vented)
Pressure Rating 150 psi @ 73° F

A = 6- 3/16

B = 6- 7/8

C = 10-11/16

Cv = 974
Values

D = 5- 7/8

E = 7- 5/8

F = 7- 1/2

G = 6-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch


L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

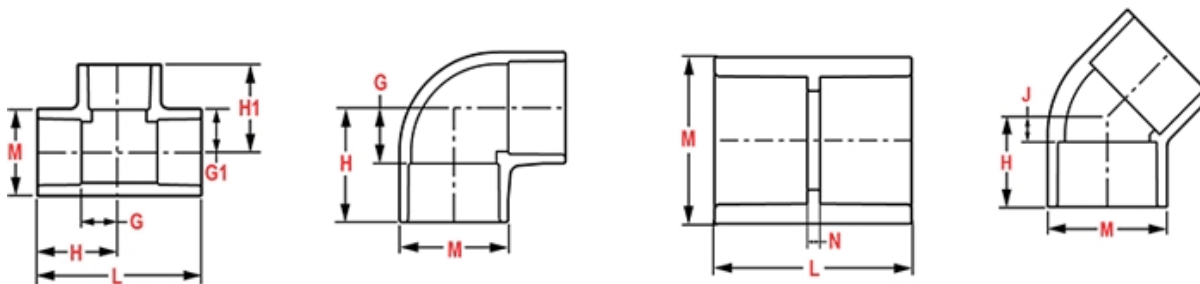

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006