

Part No: 1833V-060

Valves

True Union Ball Valve

Desc: 6 PVC TU2K IND B/V FLANGED FKM VENTED

MSRP: 5137.43

Part Code: 612

Weight(lbs): 49.022


Weight(kg): 22.236

Weight(gm): 22236

Size: 6

Color: GRAY

Material: PVC

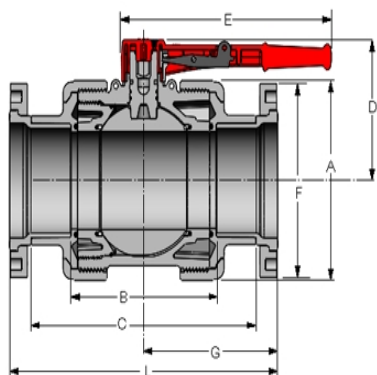

Type TU 2000 - Industrial
O-Ring FKM
Connection Flanged (Vented)
Pressure Rating 150 psi @ 73° F

A = 11- 5/8

B = 11- 9/32

C = 17-1/8

D = 8- 1/8

E = 14- 5/16

F = 11

L = 20-3/8

G = 10- 3/16

Cv = 4824
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

