

Part No: 1837-007C

Valves

True Union Ball Valve

Desc: 3/4 CPVC TU2K IND BALL VLV SPIGOT FKM

MSRP: 154.29

Part Code: 602

Weight(lbs): 0.637


Weight(kg): 0.289

Weight(gm): 289

Size: 3/4"

Color: GRAY

Material: CPVC

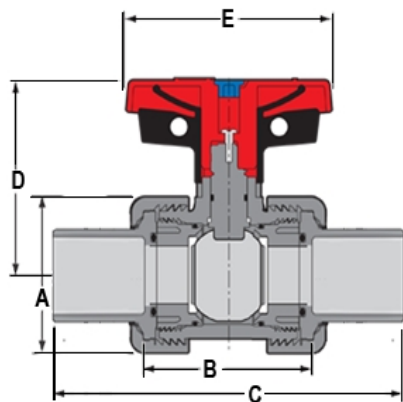

Type TU 2000 - Industrial
O-Ring FKM
Connection Spigot
Pressure Rating 235 psi @ 73° F

A = 2- 1/4

B = 3- 1/4

C = 5- 1/4

D = 2- 7/8

E = 3- 5/16

Cv = 57

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

