

Part No: 1837-030

Valves

True Union Ball Valve

Desc: 3 PVC TU2K IND BALL VALVE SPIGOT FKM

MSRP: 532.27

Part Code: 601

Weight(lbs): 8.142


Weight(kg): 3.693

Weight(gm): 3693

Size: 3"

Color: GRAY

Material: PVC

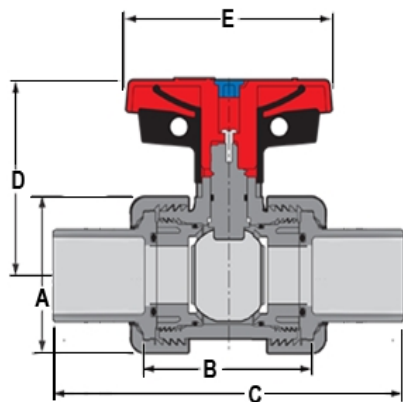

Type TU 2000 - Industrial
O-Ring FKM
Connection Spigot
Pressure Rating 235 psi @ 73° F

A = 6- 3/16

B = 7-13/16

C = 11- 9/16

D = 5- 7/8

E = 7- 5/8

Cv = 1322

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

