

Part No: 1839-007BL

Low Extractable

Valves

Desc: 3/4 PVC LE TU2K INDBALVLV SOC/FPT FKM

MSRP: 217.03

Part Code: 066

Weight(lbs): 0.657


Weight(kg): 0.298

Weight(gm): 298

Size: 3/4"

Color: BLUE

Material: PVC LE

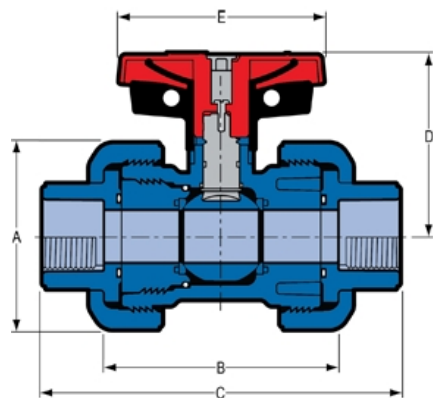

A = 2-3/8

B = 2-13/16

C = 4-13/16

D = 2- 7/8

E = 3- 3/8

Cv = 63

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

