

Part No: 183901-005BL

Low Extractable

Valves

Desc: 1/2 PVC LE TEE VALVE SOC/FPT FKM

MSRP: 629.29

Part Code: 066

Weight(lbs): 0.805


Weight(kg): 0.365

Weight(gm): 365

Size: 1/2

Color: BLUE

Material: PVC LE

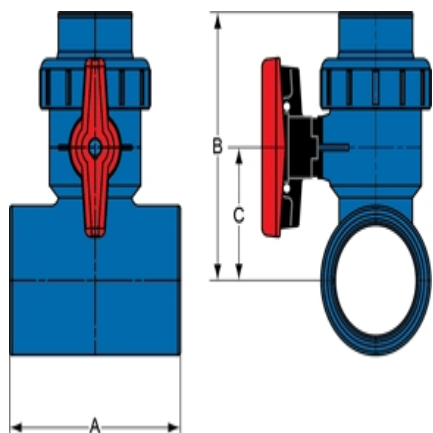

A = 2-5/16

B = 3-3/4

C = 1-5/8

Type TU 2000 TEE-Style Valve
Connection Mainline Tee X Socket/Fipt
O-Ring FKM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

