

**Part No:** 183901-166BL

**Low Extractable**

**Valves**

**Desc:** 1-1/4X1/2 PVC LE TEE VALVE S

**MSRP:** 706.32

**Part Code:** 066

**Weight(lbs):** 1.111


**Weight(kg):** 0.504

**Weight(gm):** 504

**Size:** 1-1/4 X 1/2

**Color:** BLUE

**Material:** PVC LE

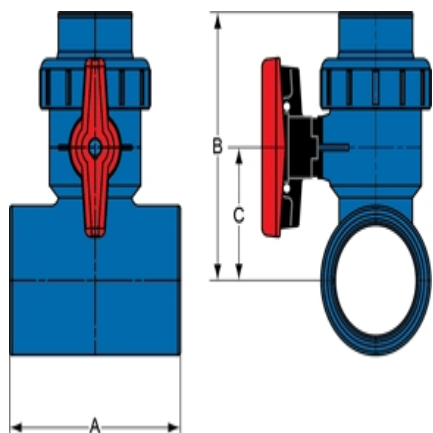

**A** = 4-1/4

**B** = 4

**C** = 1-7/8

**Type** TU 2000 TEE-Style Valve

**Connection** Mainline Tee X Socket/Fipt

**O-Ring** FKM

**Pressure Rating** 235 psi @ 73° F

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

