

Part No: 183901-168

Valves

True Union Ball Valve

Desc: 1-1/4X1 PVC TEE VALVE SOC/FPT FKM

MSRP: 368.53

Part Code: 263

Weight(lbs): 1.638

Weight(kg): 0.743

Weight(gm): 743

Size: 1-1/4"X1"

Color: GRAY


Material: PVC

Type TU 2000 - Tee Style

O-Ring FKM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

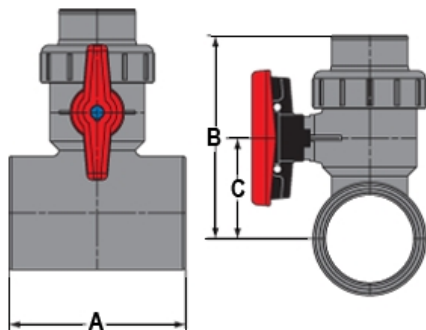

A = 4- 1/4

B = 4-13/16

C = 2- 3/16

Cv = 120
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

