

Part No: 183901-209BL

Low Extractable

Valves

Desc: 1-1/2X1/2 PVC LE TEE VALVE SOC/FPT FKM

MSRP: 706.32

Part Code: 066

Weight(lbs): 0.827


Weight(kg): 0.375

Weight(gm): 375

Size: 1-1/2 X 1/2

Color: BLUE

Material: PVC LE

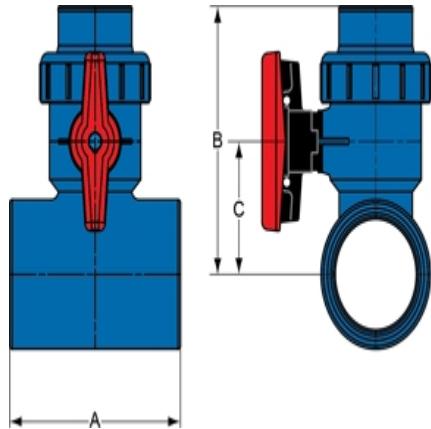

A = 4-3/8

B = 4-1/4

C = 2-1/8

Type TU 2000 TEE-Style Valve
Connection Mainline Tee X Socket/Fipt
O-Ring FKM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

