

Part No: 183901-247

Valves

True Union Ball Valve

Desc: 2X1/2 PVC TEE VALVE SOC/FPT FKM

MSRP: 413.44

Part Code: 263

Weight(lbs): 0.981

Weight(kg): 0.445

Weight(gm): 445

Size: 2"X1/2"

Color: GRAY


Material: PVC

Type TU 2000 - Tee Style

O-Ring FKM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

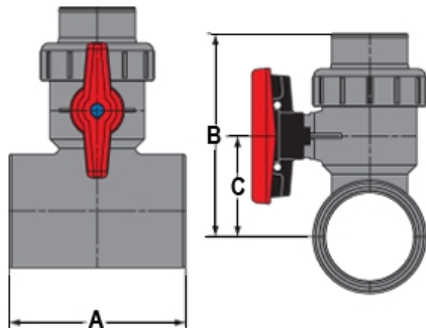

A = 4- 3/16

Cv = 29
Values

B = 4- 9/16

C = 2- 7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

