

Part No: 183901-248C

Valves

True Union Ball Valve

Desc: 2X3/4 CPVC TEE VALVE SOC/FPT FKM

MSRP: 498.76

Part Code: 264

Weight(lbs): 1.413

Weight(kg): 0.641

Weight(gm): 641

Size: 2"X3/4"

Color: GRAY


Material: CPVC

Type TU 2000 - Tee Style

O-Ring FKM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

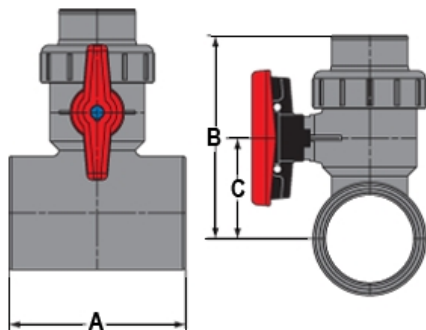

A = 4- 3/8

B = 4-15/16

C = 2- 9/16

Cv = 63
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

