

Part No: 183901-251BL

Low Extractable

Valves

Desc: 2X1-1/2 PVC LE TEE VALVE SOC/FPT FKM

MSRP: 1220.27

Part Code: 066

Weight(lbs): 3.823


Weight(kg): 1.734

Weight(gm): 1734

Size: 2 X 1-1/2

Color: BLUE

Material: PVC LE

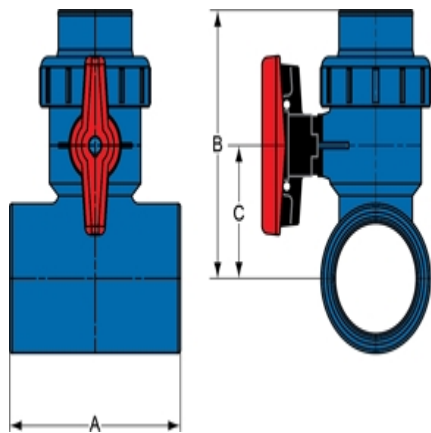

B = 6-1/16

C = 2-15/16

A = 5-7/8

Type TU 2000 TEE-Style Valve
Connection Mainline Tee X Socket/Fipt
O-Ring FKM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

