

Part No: 183901-338C

Valves

True Union Ball Valve

Desc: 3X2 CPVC TEE VALVE SOC/FPT FKM

MSRP: 1132.78

Part Code: 264

Weight(lbs): 5.765

Weight(kg): 2.615

Weight(gm): 2615

Size: 3"X2"

Color: GRAY


Material: CPVC

Type TU 2000 - Tee Style

O-Ring FKM

Connection Mainline Tee x Socket/Fipt

Pressure Rating 235 psi @ 73° F

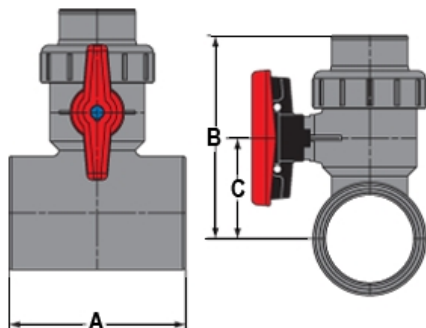

A = 6-11/16

B = 7-11/16

C = 3-13/16

Cv = 599
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

