

Part No: 183901-578BL

Low Extractable

Valves

Desc: 8X2 PVC LE TEE VALVE SOC/FPT FKM

MSRP: 2837.46

Part Code: 066

Weight(lbs): 20.937


Weight(kg): 9.497

Weight(gm): 9497

Size: 8 X 2

Color: BLUE

Material: PVC LE

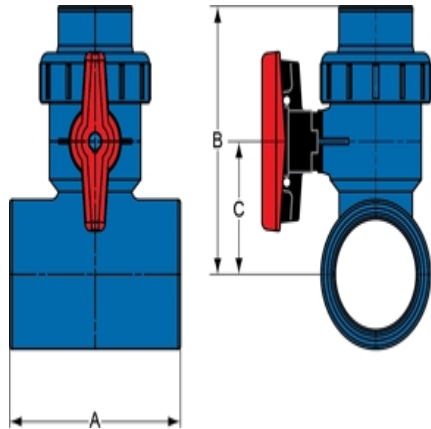

A = 15-5/8

B = 12-5/8

C = 8-3/4

Type TU 2000 TEE-Style Valve
Connection Mainline Tee X Socket/Fipt
O-Ring FKM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

